


**Axial kit**  
**EAMM-A-P6-38A-58AA**  
Part number: 8123494

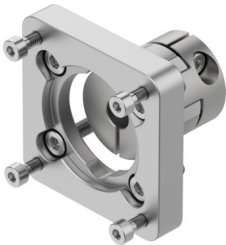

**Data sheet**

| Feature                  | Value          |
|--------------------------|----------------|
| Mounting position        | Any            |
| LABS (PWIS) conformity   | VDMA24364-B2-L |
| Storage temperature      | -25 °C...60 °C |
| Relative air humidity    | 0 - 95 %       |
| Degree of protection     | IP40           |
| Ambient temperature      | -10 °C...60 °C |
| Transferable torque      | 6.5 Nm         |
| Product weight           | 133 g          |
| Interface code, actuator | P6-38A         |
| Interface code, motor in | 58AA           |
| Note on materials        | RoHS-compliant |