


Manifold block

VABS-S7-RB-B-G14-VDE2-R12

Part number: 8141067

FESTO

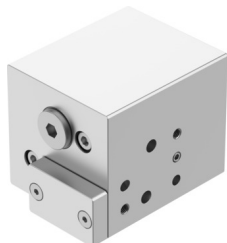

Data sheet

| Feature | Value |
|----------------------------------|---|
| Mounting position | Any |
| Pilot air supply port | External Internal |
| Operating pressure | 0 MPa...1 MPa 0 bar...10 bar |
| Operating medium | Compressed air as per ISO 8573-1:2010 [:::] |
| Corrosion resistance class (CRC) | 4 - Particularly high corrosion stress |
| LABS (PWIS) conformity | VDMA24364 zone III |
| Degree of protection | IP65 In mounted state |
| Product weight | 750 g |
| Type of mounting | With through-hole |
| Pilot air port 12 | G1/4 |
| Pneumatic connection 1 | G1/4 |
| Pneumatic connection 2 | VDI/VDE 3847 (NAMUR) |
| Pneumatic connection 3 | G1/4 |
| Note on materials | RoHS-compliant |
| Material of sub-base | Aluminum, ematal coated |
| Seals material | NBR |