


Gear unit
EMGA-40-P-G8-SST-42
Part number: 8141762

FESTO

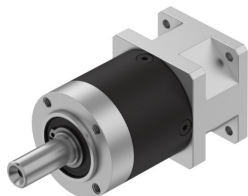

Data sheet

Feature	Value
Gearbox flange size	40 mm
Motor flange size	42 mm
Torsional backlash	0.25 deg
Gearbox type	Planetary gear
Gear ratio	8:1
Max. actuator speed	18000 rpm
Gearbox operating temperature	-25 °C...90 °C
LABS (PWIS) conformity	VDMA24364-B2-L
Degree of protection	IP54
Continuous output torque	6 Nm
Mass moment of inertia, gearbox	0.015 kgcm ²
Max. output torque	10 Nm
Max. efficiency	96 %
Torsional rigidity	0.8 Nm/arcmin
Product weight	400 g
Gearbox interface, output shaft	40G
Gearbox interface, actuator	42A
Note on materials	RoHS-compliant