


Power supply unit CACN-11A-7-20-G2

Part number: 8149585

FESTO

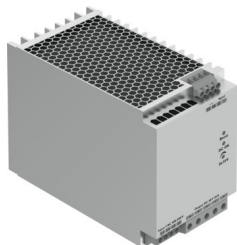

Data sheet

Feature	Value
Width	96 mm
Height	130 mm
Length	179 mm
Mounting position	Free convection
Primary supply	3-phase
Input current	1.7 - 2.1 A
Nominal output voltage DC	48 V
Nominal output current	20 A
Input voltage range AC	400 V...500 V
Power failure buffering	25 ms
Mains frequency	45 Hz...65 Hz
Certification	c UL us - Listed (OL)
CE marking (see declaration of conformity)	As per EU EMC directive As per EU low voltage directive
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-40 °C...85 °C
Relative air humidity	95 %
Degree of protection	IP20
Ambient temperature	-25 °C...70 °C
Product weight	2500 g
Type of mounting	With H-rail
Note on materials	RoHS-compliant