


**Axial kit**  
**EAMM-A-K62-150A**  
Part number: 8157271

**FESTO**

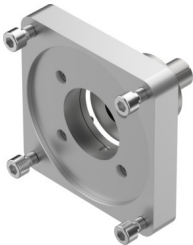

**Data sheet**

| Feature                  | Value          |
|--------------------------|----------------|
| Mounting position        | Any            |
| LABS (PWIS) conformity   | VDMA24364-B2-L |
| Storage temperature      | -25 °C...60 °C |
| Relative air humidity    | 0 - 95 %       |
| Degree of protection     | IP40           |
| Ambient temperature      | -10 °C...60 °C |
| Transferable torque      | 47 Nm          |
| Product weight           | 1672 g         |
| Interface code, actuator | K62            |
| Interface code, motor in | 140A<br>150A   |
| Note on materials        | RoHS-compliant |