


# Axial kit EAMM-A-D100-150A-S1

Part number: 8157276

FESTO

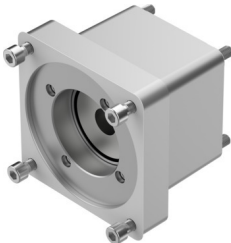

## Data sheet

| Feature                  | Value                 |
|--------------------------|-----------------------|
| Nominal length           | 103 mm                |
| Mounting position        | Any                   |
| Max. rotational speed    | 4500 rpm              |
| LABS (PWIS) conformity   | VDMA24364-B2-L        |
| Storage temperature      | -25 °C...60 °C        |
| Relative air humidity    | 0 - 95 %              |
| Degree of protection     | IP65                  |
| Ambient temperature      | -10 °C...60 °C        |
| Mass moment of inertia   | 280 kgmm <sup>2</sup> |
| Transferable torque      | 143 Nm                |
| Product weight           | 3444 g                |
| Interface code, actuator | D100                  |
| Interface code, motor in | 140A<br>150A          |
| Note on materials        | RoHS-compliant        |