


Parallel kit
EAMM-U-145-D80-150A-188-S1
Part number: 8157286

FESTO

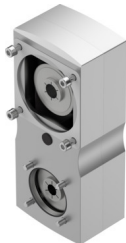

Data sheet

Feature	Value
Size	145
Mounting position	Any
Gear ratio	1:1
Max. rotational speed	4000 rpm
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP65
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	2259 kgmm ²
No-load driving torque	2 Nm
Transferable torque	50 Nm
Product weight	11600 g
Interface code, actuator	D80B
Interface code, motor in	140A 150A
Note on materials	RoHS-compliant