


Sub-base
VMPA14-AP-4-EMG-D2-8-S
Part number: 8157742

FESTO

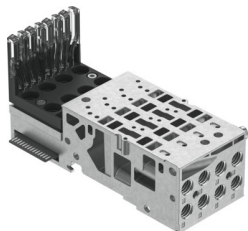

Data sheet

Feature	Value
Width	65.5 mm
Length	107.3 mm
Width dimension	14 mm
Max. no. of valve positions	4
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Pilot pressure MPa	0.3 MPa...0.8 MPa
Pilot pressure	3 bar...8 bar
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C...60 °C
Ambient temperature	-5 °C...50 °C
Product weight	320 g
Pneumatic connection 2	G1/8
Pneumatic connection 4	G1/8
Note on materials	RoHS-compliant
Material of sub-base	Die-cast aluminum