


Axial kit
EAMM-A-D60-92RA
Part number: 8159834

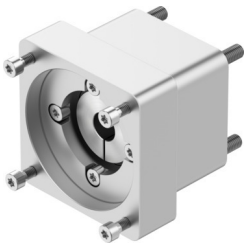

Data sheet

Feature	Value
Mounting position	Any
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Transferable torque	21 Nm
Product weight	1076 g
Interface code, actuator	D60
Interface code, motor in	92RA
Note on materials	RoHS-compliant