


Exhaust plate VABF-XA-12-M1-C

Part number: 8191741

FESTO

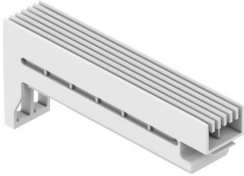

Data sheet

Feature	Value
Pack size	1
Compatible with	Valve terminal VTUX-A-P Valve terminal VTUX-A-S
Burst pressure	17 bar
Operating pressure	-0.1 MPa...0.7 MPa -1 bar...7 bar
Suitability for vacuum	no
Standard flow rate	5200 l/min
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C...70 °C
Noise level	95 dB(A)
Sound power level at a distance of 1 m	106 dB(A)
Product weight	24.9 g
Type of mounting	Engaging
Note on materials	RoHS-compliant
Housing material	PA-reinforced
Muffler material	PE