


Blanking plug NPQX-P-PC15

Part number: 8191751

FESTO

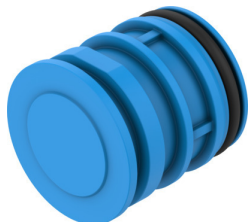

Data sheet

Feature	Value
Size	Standard
Mounting position	Any
Pack size	10
Operating pressure	-0.1 MPa...1 MPa -1 bar...10 bar -14.5 psi...145 psi
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	3 - High corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Product weight	1.6 g
Type of mounting	With retaining clamp
Note on materials	RoHS-compliant
Blanking plug material	PA-reinforced
O-ring material	HNBR