


Manifold sub-base VABX-A-ER-E12-JHTH-XR

Part number: 8191781

FESTO

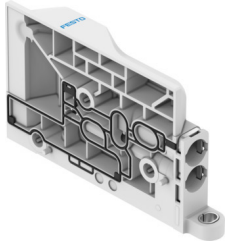

Data sheet

Feature	Value
Integrated function	Coding cover for determining the control air supply (internal or external)
Flow direction	Reversible
Compatible with	Valve terminal VTUX-A-P Valve terminal VTUX-A-S
Suitability for vacuum	yes
Dimensions W x L x H	15.05 mm x 104.3 mm x 66.55 mm
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C...70 °C
Ambient temperature	-5 °C...50 °C
Max. tightening torque for wall mounting	6 Nm
Product weight	57.9 g
Sub-base mounting type	With through-hole
Pilot air port 12/14	for 12 mm cartridge
Pilot exhaust air port 82/84	for 12 mm cartridge
Note on materials	RoHS-compliant
Seals material	NBR
Housing material	PA-reinforced
Sleeve material	High-alloy stainless steel
Clip material	High-alloy stainless steel