


Plate VABF-XA-12-M2-QX

Part number: 8191794

FESTO

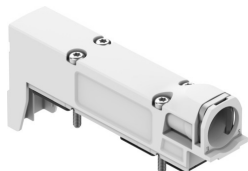

Data sheet

Feature	Value
Pack size	1
Flow direction	Reversible
Compatible with	Valve terminal VTUX-A-P Valve terminal VTUX-A-S
Operating pressure	-0.1 MPa...0.7 MPa -1 bar...7 bar
Suitability for vacuum	yes
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C...70 °C
Nominal tightening torque	0.8 Nm
Tolerance for nominal tightening torque	± 10%
Product weight	34.7 g
Type of mounting	Threaded
Pneumatic port 3/5 combined	For 15 mm cartridge
Note on materials	RoHS-compliant
Seals material	NBR
Housing material	PA-reinforced
Clip material	High-alloy stainless steel
Material of screws	Stainless steel