


**Axial kit**  
**EAMM-A-L48-60P**  
Part number: 8197450

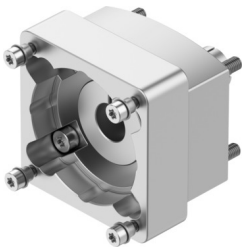

**Data sheet**

| Feature                  | Value                  |
|--------------------------|------------------------|
| Nominal length           | 41 mm                  |
| Mounting position        | Any                    |
| Max. rotational speed    | 8000 rpm               |
| LABS (PWIS) conformity   | VDMA24364-B2-L         |
| Storage temperature      | -25 °C...60 °C         |
| Relative air humidity    | 0 - 95 %               |
| Degree of protection     | IP40                   |
| Ambient temperature      | -10 °C...60 °C         |
| Mass moment of inertia   | 14.5 kgmm <sup>2</sup> |
| Transferable torque      | 12.5 Nm                |
| Product weight           | 279 g                  |
| Interface code, actuator | L48                    |
| Interface code, motor in | 60P<br>60PA            |
| Note on materials        | RoHS-compliant         |