


Guide unit
FEN-12/16-125-GF
Part number: 8204044

FESTO

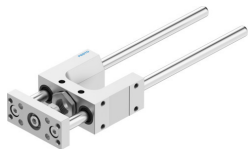

Data sheet

Feature	Value
Size	12/16
Stroke	125 mm
Mounting position	Any
Guide	Sliding guide
Structural design	Guide
Explosion prevention and protection	Observe the information on the certificate
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-20 °C...80 °C
Displacement force	15 N
Moving mass	311 g
Product weight	640 g
Type of mounting	With internal thread
Note on materials	RoHS-compliant
Material of guide component	High-alloy steel
Housing material	Wrought aluminum alloy, anodized
Material of yoke plate	Wrought aluminum alloy, anodized