


**Coupling hub**  
**EAMC-H-25-10-GB8-11**  
Part number: 8228652

**FESTO**

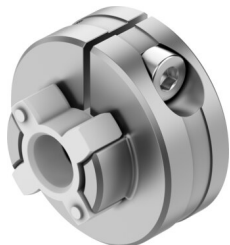

**Data sheet**

| Feature                | Value                  |
|------------------------|------------------------|
| Diameter of holder 1   | 11 mm                  |
| Size                   | 15/25                  |
| Nominal length         | 15.4 mm                |
| Mounting position      | Any                    |
| Max. rotational speed  | 10000 rpm              |
| LABS (PWIS) conformity | VDMA24364-B2-L         |
| Storage temperature    | -25 °C...60 °C         |
| Relative air humidity  | 0 - 95 %               |
| Ambient temperature    | -25 °C...60 °C         |
| Mass moment of inertia | 1.04 kgmm <sup>2</sup> |
| Transferable torque    | 2 Nm                   |
| Product weight         | 12 g                   |
| Note on materials      | RoHS-compliant         |