


# Bulkhead quick connector SCK-PK-6

Part number: 9422

FESTO

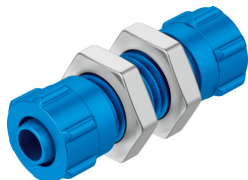

## Data sheet

Feature	Value
Nominal width	5.3 mm
Mounting position	Any
Design	Bulkhead
Pack size	10
Operating pressure for entire temperature range	0 MPa...1.6 MPa 0 bar...16 bar 0 psi...232 psi
Operating medium	Compressed air as per ISO 8573-1:2010 [7::-]
Information on operating and pilot media	Operation with oil lubrication possible
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 °C...150 °C
Pneumatic connection 1	for pneumatic tubing outside diameter 8 mm For barbed fitting, inside diameter 6 mm, with union nut
Pneumatic connection 2	for pneumatic tubing outside diameter 8 mm for barbed fitting, inside diameter 6 mm, with nut
Material of union nut	Wrought aluminum alloy, anodized
Note on materials	RoHS-compliant
Nut material	Steel, galvanized
Connector material	Wrought aluminum alloy, anodized