


Micro-ventil cu tachet SO-3-PK-3-B

Numar piesa: 10403

FESTO

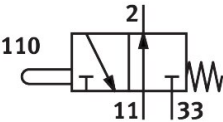

Fisa de date

Caracteristica	Valoare
Functie de ventil	deschis 3/2 monostabil
Tip de actionare	mecanic
Debit nominal standard (normalizat conform DIN 1343)	60 l/min
Racord pneumatic de lucru	PK-3
Presiune de lucru	-0.95 bar...8 bar
Tip de revenire	arc mecanic
Latimea nominala	1.8 mm
Tipul de comanda	direct
Conformitatea LABS	VDMA24364 zona III
Temperatura ambianta	-10 °C...60 °C
Forta de actionare	6 N
Greutate produs	7 g
Tipul de montare	cu orificiu de trecere
Conector pneumatic 1	PK-3
Conexiune pneumatica 2	PK-3
Material carcasa	Alama POM