


Ventil cu parghie oscilanta RW/O-3-PK-3

Numar piesa: 10750

FESTO

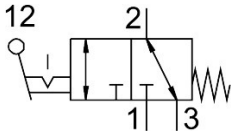

Fisa de date

Caracteristica	Valoare
Functie de ventil	3/2 deschis / inchis monostabil
Tip de actionare	mecanic
Debit nominal standard (normalizat conform DIN 1343)	80 l/min
Racord pneumatic de lucru	PK-3
Presiune de lucru	0 bar...8 bar
Structura constructiva	Scaunul pistonului
Latimea nominala	2.5 mm
Tipul de comanda	direct
Mediu de operare	Aer comprimat conform ISO 8573-1:2010 [-:::-]
Conformitatea LABS	VDMA24364-B1/B2-L
Temperatura ambianta	-10 °C...60 °C
Tipul de montare	cu orificiu de trecere
Conector pneumatic 1	PK-3
Conexiune pneumatica 2	PK-3
Conector pneumatic 3	PK-3
Material garnituri	NBR
Material carcasa	POM