


## Set axial EAMM-A-D19-28A

Numar piesa: 1081659

**FESTO**

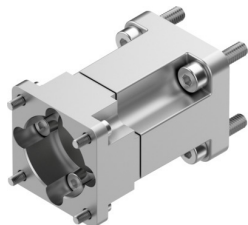

### Fisa de date

| Caracteristica               | Valoare                |
|------------------------------|------------------------|
| Lungime nominala             | 46.2 mm                |
| Pozitie de instalare         | orice                  |
| Turatie max.                 | 10000 1/min            |
| Conformitatea LABS           | VDMA24364 zona III     |
| Temperatura de depozitare    | -25 °C...60 °C         |
| Umiditate relativa           | 0 - 95 %               |
| Tip de protectie             | IP40                   |
| Temperatura ambianta         | -10 °C...60 °C         |
| Momentul de inertie al masei | 0.28 kgmm <sup>2</sup> |
| Cuplu transmisibil           | 1.1 Nm                 |
| Greutate produs              | 80 g                   |
| Cod de interfata actuator    | D19                    |
| Codul interfetei motor In    | 28A                    |
| Nota privind materialele     | Conform RoHS           |