


Amortizor de soc DYSR-16-20-Y5-T

Numar piesa: 1138645

FESTO

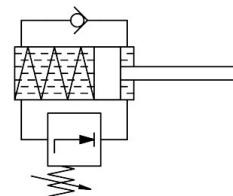

Fisa de date

Caracteristica	Valoare
Dimensiune	16
Cursa	20 mm
Amortizare	reglabil
Pozitie de instalare	orice
Detectarea pozitiei	fara
Viteza max. de impact	3 m/s
Timp de resetare la temperatura camerei	0.3 s
Timp de resetare la temperatura ambientala minima	1 s
Mod de functionare	cu apasare cu simpla actiune
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-10 °C...80 °C
Lungime de amortizare	20 mm
Forta max. de ridicare	1600 N
Consumul max. de energie pe cursa	32 J
Consum max. de energie pe ora	100000 J
Energie reziduala max.	0.16 J
Forta de restabilire	5.4 N
Forta minima de insertie	66 N
Greutate produs	250 g
Interval de masa	160 kg
Tipul de montare	cu piulita de blocare
Nota privind materialele	Conform RoHS
Material garnituri	NBR
Material carcasa	Otel galvanizat
Material tija de piston	otel inalt aliat, calit