


Amortizor de soc YSRW-DGC-40/50-B

Numar piesa: 1232870

FESTO

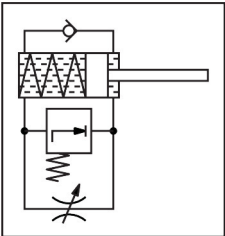

Fisa de date

Caracteristica	Valoare
Dimensiune	40 50
Amortizare	autoreglare caracteristica slaba
Pozitie de instalare	orice
Detectarea pozitiei	fara
Viteza max. de impact	3 m/s
Mod de functionare	cu apasare cu simpla actiune
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-10 °C...80 °C
Tipul de montare	cu piulita de blocare
Nota privind materialele	Conform RoHS
Material tija de piston	otel aliaj inalt