


Set axial EAMM-A-D32-40A-S1

Numar piesa: 1322178

FESTO

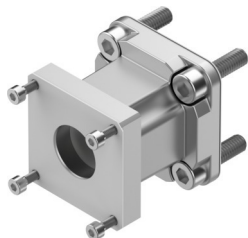

Fisa de date

Caracteristica	Valoare
Lungime nominala	41.3 mm
Pozitie de instalare	orice
Turatie max.	10000 1/min
Conformitatea LABS	VDMA24364 zona III
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP65
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	0.28 kgmm ²
Cuplu transmisibil	1.6 Nm
Greutate produs	130 g
Cod de interfata actuator	D32
Codul interfetei motor In	40A
Nota privind materialele	Conform RoHS