


Set paralel EAMM-U-110-D60-60G-120-S1

Numar piesa: 1436183

FESTO

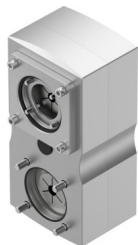

Fisa de date

Caracteristica	Valoare
Dimensiune	110
Pozitie de instalare	orice
Raportul de transmisie	1:1
Turatie max.	5000 1/min
Conformitatea LABS	VDMA24364 zona III
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP65
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	799 kgmm ²
Cuplu de antrenare in gol	0.3 Nm
Cuplu transmisibil	25 Nm
Greutate produs	5280 g
Cod de interfata actuator	D60B
Codul interfetei motor In	60G
Nota privind materialele	Conform RoHS