


Set axial EAMM-A-S38-67A-G2

Numar piesa: 1456638

FESTO

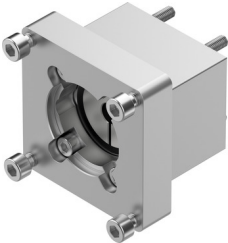

Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Cuplu transmisibil	6.5 Nm
Greutate produs	490 g
Cod de interfata actuator	S38
Codul interfetei motor In	67A
Nota privind materialele	Conform RoHS