


Modul prindere EV-32-5

Numar piesa: 150685

FESTO

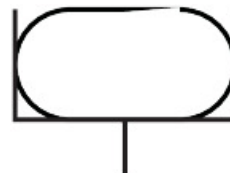

Fisa de date

Caracteristica	Valoare
Cursa	5 mm
Suprafata de prindere	Ø 32
Pozitie de instalare	orice
Mod de functionare	cu simpla actiune
Presiune de lucru	0.6 MPa 6 bar 87 psi
Mediu de operare	Aer comprimat conform ISO 8573-1:2010 [7:-:-]
Conformitatea LABS	VDMA24364-B1/B2-L
Temperatura ambianta	-10 °C...40 °C
Greutate produs	34 g
Tipul de montare	cu orificiu de trecere
Conexiune pneumatica	M3
Material carcasa	Aluminiu turnat sub presiune
Material membrana	TPE-U (PU)