


Flansa oscilanta SNGL-160

Numar piesa: 151534

FESTO

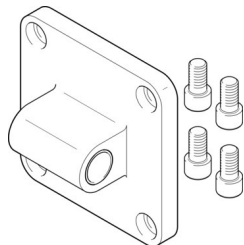

Fisa de date

Caracteristica	Valoare
Dimensiune	160
Conform cu standardul	ISO 15552 (anterior si VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-40 °C...90 °C
Greutate produs	2358 g
Material fixare	Aluminiu turnat sub presiune
Material rulment	Material plastic
Material suruburi	Otel galvanizat