


# Set paralel EAMM-U-50-D32-32B-78

Numar piesa: 1570862

FESTO

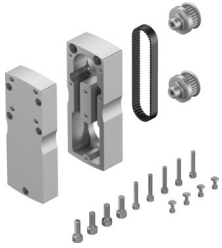

## Fisa de date

Caracteristica	Valoare
Dimensiune	50
Pozitie de instalare	orice
Raportul de transmisie	1:1
Turatie max.	6000 1/min
Conformitatea LABS	VDMA24364 zona III
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	12.1 kgmm <sup>2</sup>
Cuplu de antrenare in gol	0.01 Nm
Cuplu transmisibil	1 Nm
Greutate produs	608 g
Cod de interfata actuator	D32B
Codul interfetei motor In	32B
Nota privind materialele	Conform RoHS