


Flansa oscilanta SNGB-250

Numar piesa: 157512

FESTO

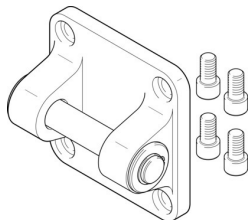

Fisa de date

Caracteristica	Valoare
Dimensiune	250
Pe baza standardului	ISO 15552 (anterior si VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-40 °C...90 °C
Greutate produs	16141 g
Nota privind materialele	Conform RoHS
Material fixare	Fonta ductila
Material bolt	Otel galvanizat
Material rulment	Material plastic
Material saiba	Otel galvanizat
Material suruburi	Otel galvanizat
Material siguranta	Otel cu arc, galvanizat