


## Flansa oscilanta SZF-12

Numar piesa: 161818

FESTO

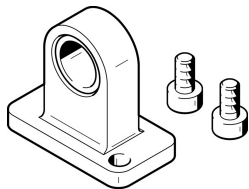

### Fisa de date

| Caracteristica                       | Valoare                                      |
|--------------------------------------|----------------------------------------------|
| Dimensiune                           | 12                                           |
| Pozitie de instalare                 | orice                                        |
| Clasa de rezistenta la coroziune KBK | 2 - Solicitare moderata din cauza coroziunii |
| Conformitatea LABS                   | VDMA24364-B1/B2-L                            |
| Temperatura ambianta                 | -40 °C...90 °C                               |
| Greutate produs                      | 20 g                                         |
| Nota privind materialele             | Conform RoHS                                 |
| Material fixare                      | otel inoxidabil aliaj inalt                  |
| Material rulment                     | Material plastic                             |
| Material suruburi                    | Otel, galvanizat                             |