


Modul ramificare FRM-1/8-D-MINI

Numar piesa: 164949

FESTO

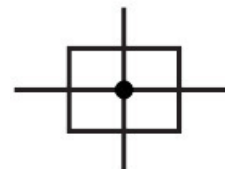

Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Structura constructiva	Modul de ramificare
Presiune de lucru	0 MPa...1.6 MPa 0 bar...16 bar
Diametru nominal normal pe directia principala de curgere 1->2	1400 l/min
Mediu de operare	Aer comprimat conform ISO 8573-1:2010 [7:-:-] Gaze inerte
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B1/B2-L
Temperatura de depozitare	-10 °C...60 °C
Clasa de puritate a aerului la iesire	Aer comprimat conform ISO 8573-1:2010 [7:-:-] Gaze inerte
Temperatura medie	-10 °C...60 °C
Temperatura ambianta	-10 °C...60 °C
Greutate produs	207 g
Conector pneumatic 1	G1/8
Conexiune pneumatica 2	G1/8
Conector pneumatic 3	G1/4
Conexiune pneumatica 4	G1/4
Nota privind materialele	Conform RoHS
Material carcasa	Zinc turnat sub presiune