 



Modul ramificare FRM-H-D-MAXI

Numar piesa: 170689

FESTO

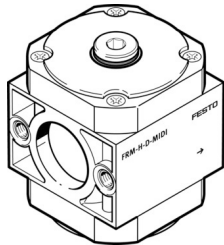

Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Structura constructiva	Modul de ramificare
Presiune de lucru	0.025 MPa...1.6 MPa 0.25 bar...16 bar
Diametru nominal normal pe directia principala de curgere 1->2	13500 l/min
Mediu de operare	Aer comprimat conform ISO 8573-1:2010 [7:-:-] Gaze inerte
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B1/B2-L
Temperatura de depozitare	-10 °C...60 °C
Clasa de puritate a aerului la iesire	Aer comprimat conform ISO 8573-1:2010 [7:-:-] Gaze inerte
Temperatura medie	-10 °C...60 °C
Temperatura ambianta	-10 °C...60 °C
Greutate produs	446 g
Conector pneumatic 3	G3/4
Conexiune pneumatica 4	G1/4
Nota privind materialele	Conform RoHS
Material carcasa	Zinc turnat sub presiune