


Regulator presiune LR-3/8-D-7-O-MINI-NPT

Numar piesa: 173655

FESTO

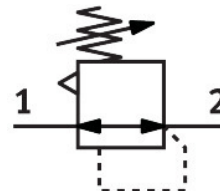

Fisa de date

Caracteristica	Valoare
Dimensiune	Mini
Seria	D
Presiune de lucru	0.1 MPa...1.6 MPa 1 bar...16 bar
Domeniu de reglare a presiunii	0.5 bar...7 bar
Histerezis max. de presiune	0.02 MPa 0.2 bar 2.9 psi
Mediu de operare	Aer comprimat conform ISO 8573-1:2010 [7:4:4] Gaze inerte
Nota referitoare la mediul de lucru/comanda	Posibilitatea operarii cu ulei (necesar pentru operare ulterioara)
Conformitatea LABS	VDMA24364-B1/B2-L
Clasa de puritate a aerului la iesire	Aer comprimat conform ISO 8573-1:2010 [7:4:4] Gaze inerte
Temperatura medie	-10 °C...60 °C
Temperatura ambianta	-10 °C...60 °C
Conector pneumatic 1	3/8 NPT
Conexiune pneumatica 2	3/8 NPT
Nota privind materialele	Conform RoHS