


Grup de preparare aer FRC-3/4-D-7-MAXI-A-NPT

Numar piesa: 173883

FESTO

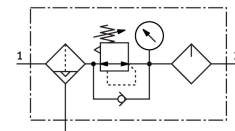

Fisa de date

Caracteristica	Valoare
Dimensiune	Maxi
Pozitie de instalare	vertical
Purjare a condensului	complet automat
Finete de filtrare	40 µm
Presiune de lucru	0.2 MPa...1.2 MPa 2 bar...12 bar
Domeniu de reglare a presiunii	0.5 bar...7 bar
Histerezis max. de presiune	0.04 MPa 0.4 bar 5.8 psi
Debit nominal standard (normalizat conform DIN 1343)	8500 l/min
Mediu de operare	Aer comprimat conform ISO 8573-1:2010 [-:::-]
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B1/B2-L
Temperatura medie	-10 °C...60 °C
Temperatura ambianta	-10 °C...60 °C
Greutate produs	2390 g
Tipul de montare	Instalarea liniei cu coltar de sustinere optional:
Conector pneumatic 1	3/4 NPT
Conexiune pneumatica 2	3/4 NPT
Material carcasa	Zinc turnat sub presiune PC