


Modul ramificare FRM-1/2-D-MIDI-NPT

Numar piesa: 173928

FESTO

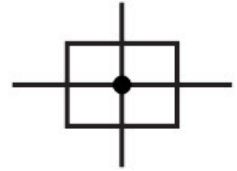

Fisa de date

| Caracteristica | Valoare |
|--|--|
| Pozitie de instalare | orice |
| Structura constructiva | Modul de ramificare |
| Presiune de lucru | 0 MPa...1.6 MPa 0 bar...16 bar |
| Diametru nominal normal pe directia principala de curgere 1->2 | 8200 l/min |
| Mediu de operare | Aer comprimat conform ISO 8573-1:2010 [7:..:] Gaze inerte |
| Clasa de rezistenta la coroziune KBK | 2 - Solicitare moderata din cauza coroziunii |
| Conformitatea LABS | VDMA24364-B1/B2-L |
| Temperatura de depozitare | -10 °C...60 °C |
| Clasa de puritate a aerului la iesire | Aer comprimat conform ISO 8573-1:2010 [7:..:] Gaze inerte |
| Temperatura medie | -10 °C...60 °C |
| Temperatura ambianta | -10 °C...60 °C |
| Greutate produs | 502 g |
| Conector pneumatic 1 | 1/2 NPT |
| Conexiune pneumatica 2 | 1/2 NPT |
| Conector pneumatic 3 | G1/2 |
| Conexiune pneumatica 4 | G1/4 |
| Nota privind materialele | Conform RoHS |
| Material carcasa | Aluminiu turnat sub presiune |