


Flansa oscilanta SNC-40

Numar piesa: 174384

FESTO

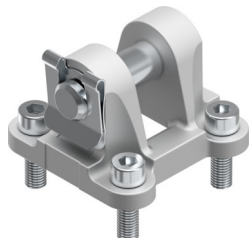

Fisa de date

Caracteristica	Valoare
Dimensiune	40
Pe baza standardului	ISO 15552 (anterior si VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-40 °C...150 °C
Sarcina admisibila maxima	1.5 kN
Greutate produs	141 g
Nota privind materialele	Conform RoHS
Material fixare	Aluminiu turnat sub presiune
Material bolt	Otel galvanizat
Material suruburi	Otel galvanizat
Material siguranta	Otel de arcuri galvanizat