


Flansa oscilanta SNCS-63

Numar piesa: 174400

FESTO

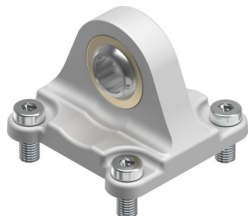

Fisa de date

Caracteristica	Valoare
Dimensiune	63
Pe baza standardului	ISO 15552 (anterior si VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-40 °C...150 °C
Sarcina admisibila maxima	4 kN
Greutate produs	281 g
Nota privind materialele	Conform RoHS
Material fixare	Aluminiu turnat sub presiune
Material rulment articulat	Otel PTFE
Material suruburi	Otel galvanizat