


Flansa oscilanta SNCS-125

Numar piesa: 174403

FESTO

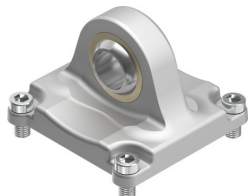

Fisa de date

Caracteristica	Valoare
Dimensiune	125
Pe baza standardului	ISO 15552 (anterior si VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-40 °C...150 °C
Greutate produs	1369 g
Nota privind materialele	Conform RoHS
Material fixare	Aliaj de aluminiu forjat
Material rulment articulat	Otel PTFE
Material suruburi	Otel galvanizat