


Flansa oscilanta SNCL-40

Numar piesa: 174405

FESTO

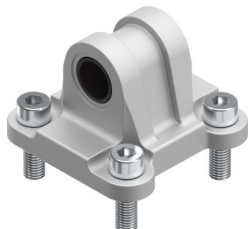

Fisa de date

Caracteristica	Valoare
Dimensiune	40
Pe baza standardului	ISO 15552 (anterior si VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-40 °C...90 °C
Sarcina admisibila maxima	1.5 kN
Greutate produs	95 g
Nota privind materialele	Conform RoHS
Material fixare	Aluminiu turnat sub presiune
Material rulment	Material plastic
Material suruburi	Otel galvanizat