


Set paralel EAMM-U-50-D32-40P-78-S1

Numar piesa: 2154009

FESTO

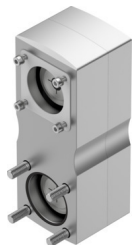

Fisa de date

Caracteristica	Valoare
Dimensiune	50
Pozitie de instalare	orice
Raportul de transmisie	1:1
Turatie max.	6000 1/min
Conformitatea LABS	VDMA24364 zona III
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP65
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	12.1 kgmm ²
Cuplu de antrenare in gol	0.01 Nm
Cuplu transmisibil	1 Nm
Greutate produs	610 g
Cod de interfata actuator	D32B
Codul interfetei motor In	40P
Nota privind materialele	Conform RoHS