


Set axial EAMM-A-D40-40G-S1

Numar piesa: 2256399

FESTO

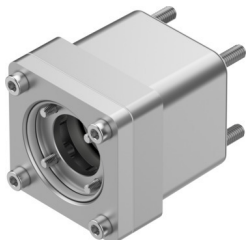

Fisa de date

Caracteristica	Valoare
Lungime nominala	63.5 mm
Pozitie de instalare	orice
Turatie max.	8000 1/min
Conformitatea LABS	VDMA24364 zona III
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP65
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	5.87 kgmm ²
Cuplu transmisibil	12.5 Nm
Greutate produs	450 g
Cod de interfata actuator	D40
Codul interfetei motor In	40G
Nota privind materialele	Conform RoHS