


Set axial EAMM-A-D60-100A-S1

Numar piesa: 2256700

FESTO

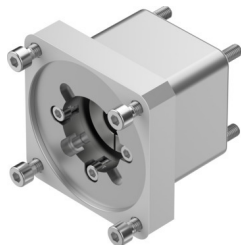

Fisa de date

Caracteristica	Valoare
Lungime nominala	79.2 mm
Pozitie de instalare	orice
Turatie max.	6000 1/min
Conformitatea LABS	VDMA24364 zona III
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP65
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	34.8 kgmm ²
Cuplu transmisibil	17 Nm
Greutate produs	1170 g
Cod de interfata actuator	D60
Codul interfetei motor In	100A
Nota privind materialele	Conform RoHS