


## Set paralel EAMM-U-60-S48-40G-91

Numar piesa: 2283760

FESTO

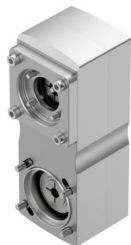

### Fisa de date

| Caracteristica               | Valoare                |
|------------------------------|------------------------|
| Dimensiune                   | 60                     |
| Pozitie de instalare         | orice                  |
| Raportul de transmisie       | 1:1                    |
| Turatie max.                 | 6000 1/min             |
| Conformitatea LABS           | VDMA24364 zona III     |
| Temperatura de depozitare    | -25 °C...60 °C         |
| Umiditate relativa           | 0 - 95 %               |
| Tip de protectie             | IP40                   |
| Temperatura ambianta         | -10 °C...60 °C         |
| Momentul de inertie al masei | 26.7 kgmm <sup>2</sup> |
| Cuplu de antrenare in gol    | 0.07 Nm                |
| Cuplu transmisibil           | 3 Nm                   |
| Greutate produs              | 1110 g                 |
| Cod de interfata actuator    | S48                    |
| Codul interfetei motor In    | 40G                    |
| Nota privind materialele     | Conform RoHS           |