


Amortizor de soc DYSC-20-18-Y1F

Numar piesa: 2479149

FESTO

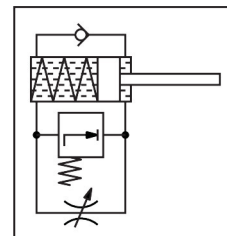

Fisa de date

Caracteristica	Valoare
Dimensiune	20
Cursa	18 mm
Amortizare	autoreglare
Pozitie de instalare	orice
Detectarea pozitiei	fara
Viteza max. de impact	3 m/s
Timp de resetare la temperatura camerei	0.3 s
Timp de resetare la temperatura ambientala minima	1 s
Mod de functionare	cu apasare cu simpla actiune
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-10 °C...80 °C
Lungime de amortizare	16 mm
Forta max. de ridicare	3000 N
Consumul max. de energie pe cursa	38 J
Consum max. de energie pe ora	80000 J
Energie reziduala max.	0.32 J
Forta de restabilire	10 N
Forta minima de insertie	100 N
Greutate produs	370 g
Interval de masa	100 kg
Tipul de montare	cu piulita de blocare
Nota privind materialele	Conform RoHS
Material garnituri	NBR
Material carcasa	Otel galvanizat
Material tija de piston	otel aliaj inalt