


Set paralel EAMM-U-86-D50-60H-102-S1

Numar piesa: 2803325

FESTO

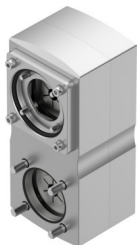

Fisa de date

Caracteristica	Valoare
Dimensiune	86
Pozitie de instalare	orice
Raportul de transmisie	1:1
Turatie max.	5000 1/min
Conformitatea LABS	VDMA24364 zona III
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP65
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	175 kgmm ²
Cuplu de antrenare in gol	0.25 Nm
Cuplu transmisibil	9.5 Nm
Greutate produs	2520 g
Cod de interfata actuator	D50B
Codul interfetei motor In	60H
Nota privind materialele	Conform RoHS