


Set axial EAMM-A-D32-60H

Numar piesa: 2946760

FESTO

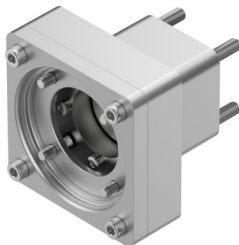

Fisa de date

Caracteristica	Valoare
Lungime nominala	66.5 mm
Pozitie de instalare	orice
Turatie max.	8000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	5.87 kgmm ²
Cuplu transmisibil	6.5 Nm
Greutate produs	540 g
Cod de interfata actuator	D32 D32C
Codul interfetei motor In	60H
Nota privind materialele	Conform RoHS