


Set axial EAMM-A-D100-120G-S1

Numar piesa: 2946765

FESTO

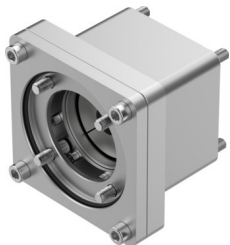

Fisa de date

Caracteristica	Valoare
Lungime nominala	115 mm
Pozitie de instalare	orice
Turatie max.	4500 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP65
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	280 kgmm ²
Cuplu transmisibil	143 Nm
Greutate produs	3520 g
Cod de interfata actuator	D100
Codul interfetei motor In	120G
Nota privind materialele	Conform RoHS