


Suport lagar LSNSG-40

Numar piesa: 31748

FESTO

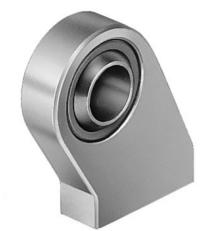

Fisa de date

Caracteristica	Valoare
Dimensiune	40
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Conformitatea LABS	VDMA24364-B1/B2-L
Temperatura ambianta	-40 °C...150 °C
Sarcina admisibila maxima	1.5 kN
Greutate produs	160 g
Nota privind materialele	Conform RoHS
Material fixare	Otel galvanizat
Material rulment articulat	Otel PTFE