


Ventil siguranta vacuum ISV-1/4

Numar piesa: 33970

FESTO

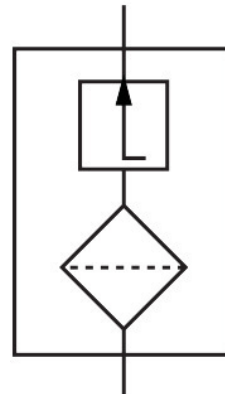

Fisa de date

Caracteristica	Valoare
Dimensiune	G1/4
Capacitate de impuls de cadere	8 MPa 8 bar
Pozitie de instalare	orice
Presiune de lucru	-95 kPa...0 kPa -0.95 bar...0 bar
Debit volumetric de aspiratie necesar, la -0,05 MPa (-0,5 bari, -7,25 psi)	1.6 l/min
Mediu de operare	Aer comprimat conform ISO 8573-1:2010 [7:::]
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-10 °C...60 °C
Greutate produs	16 g
Tipul de montare	insurubabil
Conector pneumatic 1	G1/4
Conexiune pneumatica 2	G1/4
Material arc	otel aliaj inalt
Material filtru	Aliaj de aluminiu forjat Plasa din otel inoxidabil
Material carcasa	Aliaj de aluminiu forjat
Material surub tubular	Aliaj de aluminiu forjat
Material plutitor	POM