


Cuplaj
EAMD-67-51-19-32X32-U
Numar piesa: 3398671

FESTO

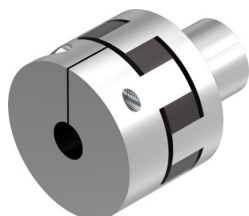

Fisa de date

Caracteristica	Valoare
Diametrul de montare 1	19 mm
Diametru de montare 2	32 mm
Dimensiune	67
Lungime nominala	51 mm
Pozitie de instalare	orice
Turatie max.	4500 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Temperatura ambianta	-25 °C...60 °C
Momentul de inertie al masei	374 kgmm ²
Cuplu transmisibil	113 Nm
Greutate produs	745 g
Nota privind materialele	Conform RoHS